

Technical data sheet

90° bend 160 FS

Item number: 6229379



90° bend, horizontal, for all wide span cable ladders of 160 mm side height.
For further stabilisation, additional supports should be planned for the area of the fittings.




St	Steel
FS	Strip galvanized

Master data

Item number	6229379
Type	WLB 90 166 FS
Description 1	90° bend
Description 2	for wide span cable ladder 160
Manufacturer	OBO
Dimension	160x600
Colour	zinc
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	1618 kg
Weight unit	kg/100 pc.

Dimensions

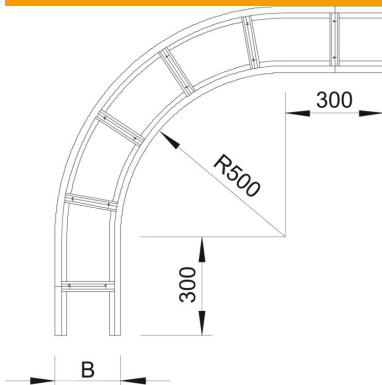

Width	600 mm
Height	160 mm
Dimension B	600 mm
Dimension R	600 mm

Technical data sheet

90° bend 160 FS

Item number: 6229379



Technical data

Bend (angle)	90°
Version of the rungs	Profile unperforated
Side rail version	Flat profile
Maintain electrical functions	no
Change of direction	Horizontal
Rustproof steel, pickled	no
Side perforation	no
Wide-span version	yes
Rail thickness	2 mm