


# Technical data sheet

## T branch piece 160 FT

Item number: 6229735

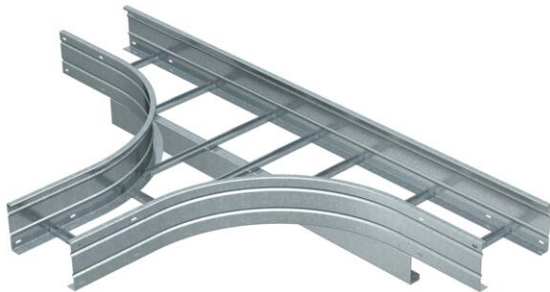

Horizontal T branch piece, for all wide span cable ladders of 160 mm side height. For further stabilisation, additional supports should be planned for the area of the fittings.




**St** Steel

**FT** Hot-dip galvanised

### Master data

Item number	6229735
Type	WLT 1630 FT
Description 1	T-branch piece
Description 2	for wide span cable ladder 160
Manufacturer	OBO
Dimension	160x300
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	2565 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	70,8929 kg CO2e / 1 Piece

### Dimensions

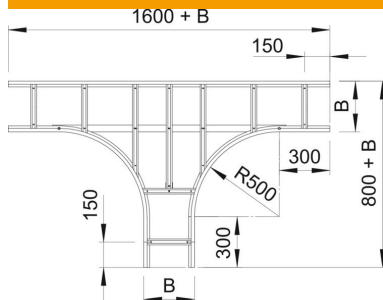

Width	300 mm
Height	160 mm
Dimension B	300 mm
Dimension R	500 mm

# Technical data sheet

T branch piece 160 FT

Item number: 6229735



## Technical data

Version of the rungs	Profile unperforated
Side rail version	Flat profile
Maintain electrical functions	no
Rustproof steel, pickled	no
Wide-span version	yes
Rail thickness	2 mm