


Technical data sheet

Fastening clip, plant standard 7855, single-lobe

Item number: 1043242

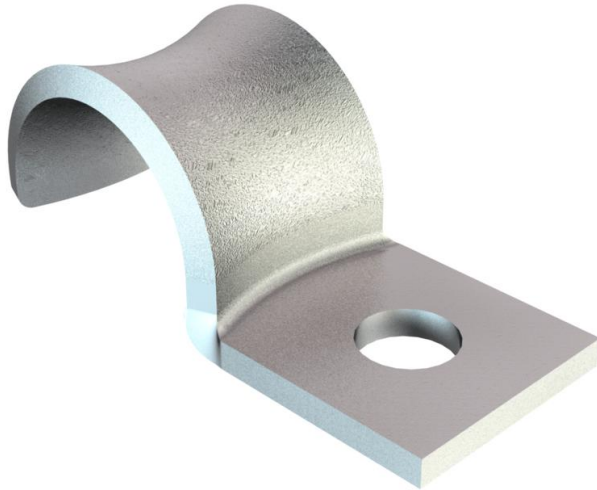

Dimensions to Siemens standard SN 78550, shape A, with strongly rounded edges, thus particularly suitable for sensitive cables.

* Sizes 2 to 10 not suitable for bolt-firing tool and nail device.



St Steel

GTP Electrogalvanized, transparently passivated

Master data

Item number	1043242
Description 1	Fastening clip
Description 2	single lobe
Manufacturer	OBO
Dimension	14mm
Material	Steel
Surface	Electrogalvanized, transparently passivated
Surface standard	
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.579 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,012 kg COe / 1 Piece


Technical data sheet

Fastening clip, plant standard 7855, single-lobe

Item number: 1043242



Dimensions

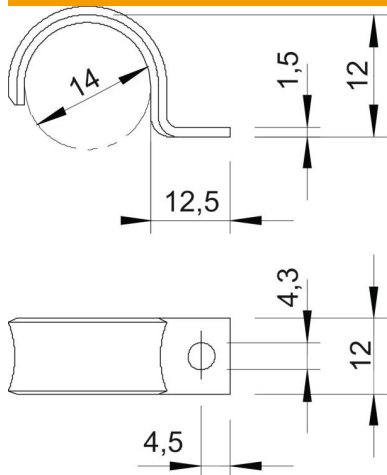

Length	12.5 mm
Width	12 mm
Height	12 mm
Dimension A	4.5 mm
Dimension b	12 mm
Dimension D	14 mm
Dimension d	4.3 mm
Dimension H	12 mm
Dimension L	12.5 mm
Dimension t	1.5 mm

Technical data

Distance to the wall	no
Number of cables/pipes	1
Version for	Single-lobe
Fastening type	Screw hole
For diameter	14
Suitable in fire protection area	no
Halogen-free	yes
Plastic-covered	no
Hole size	4,3 mm
Material thickness	1.5 mm
Nominal diameter	14 mm
UV-resistant	yes