


# Technical data sheet

## Straight connector A2

Item number: 6091229

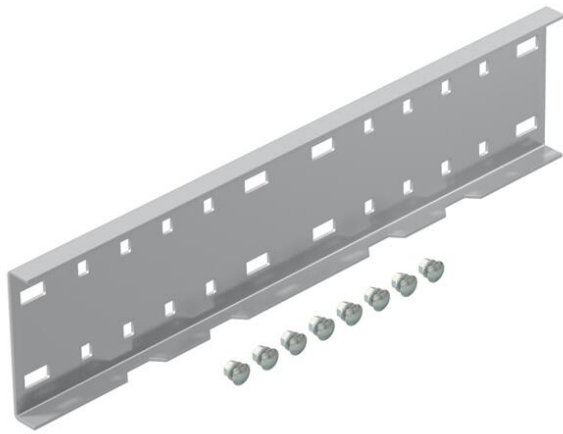

Straight connector for straight connections of cable trays, wide span cable trays and ladders with a side height of 110 mm. Including appropriate bolts, washers and nuts.



**A2** Stainless steel

**2B** Bright, treated

### Master data

Item number	6091229
Type	WRVL 110 A2
Description 1	Straight connector
Description 2	for wide span system 110
Manufacturer	OBO
Dimension	110x500
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	2
Unit of quantity	Piece
Weight	154.2 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	9,7137 kg COe / 1 Piece


# Technical data sheet

## Straight connector A2

Item number: 6091229



### Dimensions

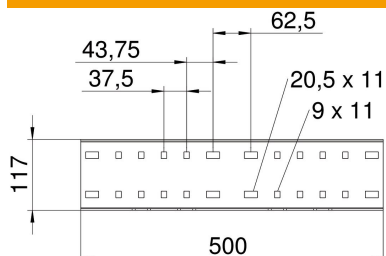

Length	500 mm
Width	20 mm
Height	110 mm
Plate thickness	2.5 mm

### Technical data

Version for	Straight connector
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	yes
Suitable for cable tray	yes
Suitable for cable tray system height	110 mm
Adjustable connector, horizontal	no
Articulated connector, vertical	no
Rustproof steel, pickled	no
Connection type	Screw connector