


# Technical data sheet

## Straight connector A4

Item number: 6227730

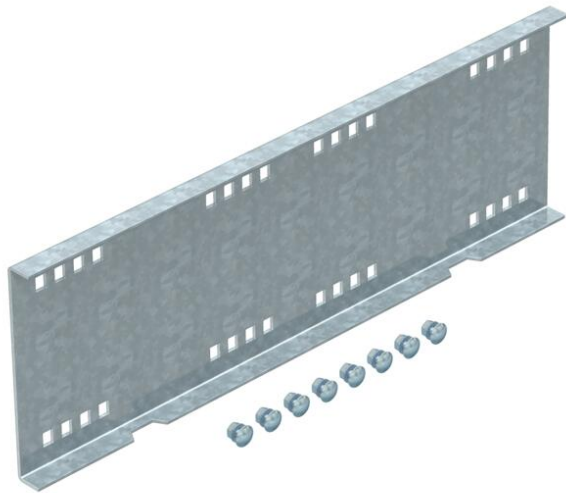

Straight connector for straight connections of cable trays, wide span cable trays and ladders with a side height of 160 mm.  
Including appropriate bolts, washers and nuts.



**A4** Stainless steel

**2B** Bright, treated

### Master data

Item number	6227730
Type	WRVL 160 A4
Description 1	Straight connector
Description 2	for wide span system 160
Manufacturer	OBO
Dimension	160x500
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	2
Unit of quantity	Piece
Weight	250 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	13,2414 kg CO2e / 1 Piece

# Technical data sheet

## Straight connector A4

Item number: 6227730



**Dimensions**

Technical drawing of the Straight connector A4 showing dimensions: Length 500 mm, Width 20 mm, Height 165.5 mm, Plate thickness 2.5 mm. The drawing also shows internal dimensions: 200 mm, 50 mm, 200 mm, and 11 mm. A small detail shows a 9 mm hole and a 20 mm flange.

Length	500 mm
Width	20 mm
Height	160 mm
Plate thickness	2.5 mm

Technical data		
Version for	Straight connector	
Maintain electrical functions	no	
Suitable for mesh cable tray	no	
Suitable for cable ladder	yes	
Suitable for cable tray	yes	
Suitable for cable tray system height	160 mm	
Adjustable connector, horizontal	no	
Articulated connector, vertical	no	
Rustproof steel, pickled	no	
Connection type	Screw connector	