

Technical data sheet

Changeover switch with LED element, 1 module

Item number: 6120940



Changeover switch with LED element as a control light, 1-pole, 10 A, 250 V~, with screwless terminals.



PC

Polycarbonate

Master data

Item number	6120940
Type	WS-UKL SWGR1
Description 1	Two-way switch
Description 2	with pilot lamp
Manufacturer	OBO
Dimension	10 A, 250 V
Colour	Black-grey; RAL 7021
Material	Polycarbonate
Smallest sales unit	1
Unit of quantity	Piece
Weight	2.3 kg
Weight unit	kg/100 pc.


Technical data sheet

Changeover switch with LED element, 1 module

Item number: 6120940



Dimensions

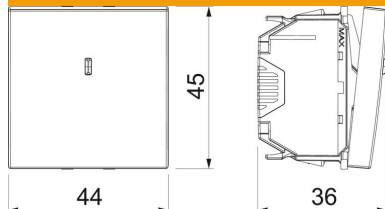

Width	45 mm
Height	45 mm

Technical data

Connection type	Screwless terminal
Surface version	Matt
Fastening type	Lock
Illumination	yes
Lighting function	Checking and orientation
Labelling panel	no
Halogen-free	yes
Warning light	yes
Mounting type	Device installation duct
Nominal voltage	250 V
Nominal current	10 A
Circuit type	Changeover switch
Protection rating	IP20
Text box/labelling area	no
Depth	36 mm