


Technical data sheet

Washer

Item number: 3402096



Washer according to DIN 125, shape A, for universal use.

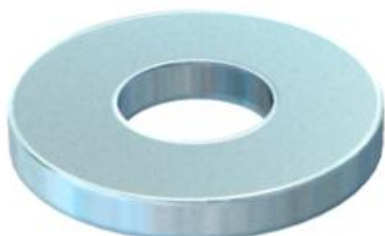

St	Steel
G	Electrogalvanized

Master data

Item number	3402096
Type	WS M10 D20 G
Description 1	Washer
Manufacturer	OBO
Dimension	M10
Material	Steel
Surface	Electrogalvanized
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.408 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,0102 kg COe / 1 Piece

Dimensions

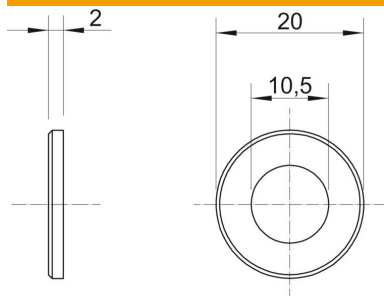


Plate thickness	0.08 in
Dimension D	0.79 in
Dimension d	0.41 in
Dimension d	10.5 mm
Dimension d min.	20 mm
Dimension h	2 mm

Technical data sheet

Washer

Item number: 3402096



Technical data

Faceted	no
Hardened	no
Thread	M10
Inner diameter	10.5 mm
Material thickness	2 mm
With tothing	no
Hole shape	Round