


# Technical data sheet

## Large washer G

Item number: 3403041



Washer of particularly large outer diameter.

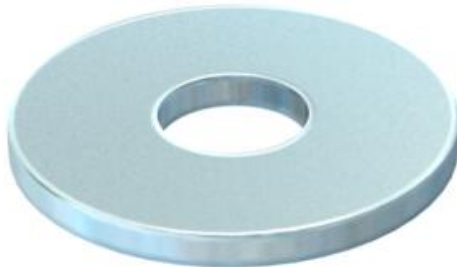


|    |                   |
|----|-------------------|
| St | Steel             |
| G  | Electrogalvanized |

### Master data

|                                   |                            |
|-----------------------------------|----------------------------|
| Item number                       | 3403041                    |
| Type                              | WS M5 G20 G                |
| Description 1                     | Fender plate               |
| Manufacturer                      | OBO                        |
| Dimension                         | M5,Ø20mm                   |
| Material                          | Steel                      |
| Surface                           | Electrogalvanized          |
| Surface standard                  | EN ISO 19598 / EN ISO 4042 |
| Smallest sales unit               | 100                        |
| Unit of quantity                  | Piece                      |
| Weight                            | 0.207 kg                   |
| Weight unit                       | kg/100 pc.                 |
| CO Footprint (GWP) Cradle-to-Gate | 0,0073 kg COe / 1 Piece    |

### Dimensions

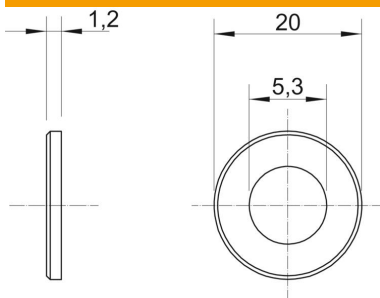

|                  |         |
|------------------|---------|
| Plate thickness  | 0.05 in |
| Dimension D      | 0.79 in |
| Dimension d      | 0.21 in |
| Dimension d      | 5.3 mm  |
| Dimension d max. | 20 mm   |
| Dimension d min. | 20 mm   |
| Dimension h      | 1.2 mm  |

# Technical data sheet

## Large washer G

Item number: 3403041



### Technical data

|                    |        |
|--------------------|--------|
| Faceted            | no     |
| Hardened           | no     |
| Thread             | M5     |
| Inner diameter     | 5.3 mm |
| Material thickness | 1.2 mm |