

# Technical data sheet

## VA roof conductor holder, pitched roofs

Item number: 5408047



- For routing of the isCon® conductor on pitched roofs
- Cable bracket with sprung discs to protect the screws against loosening



**A2** Stainless steel

### Master data

Item number	5408047
Type	isCon H280 VA
Description 1	Roof conductor holder
Description 2	for tiled roofs
Manufacturer	OBO
Dimension	280mm
Material	Stainless steel
Smallest sales unit	25
Unit of quantity	Piece
Weight	16.1 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	1,171 kg CO2e / 1 Piece


# Technical data sheet

## VA roof conductor holder, pitched roofs

Item number: 5408047



### Dimensions

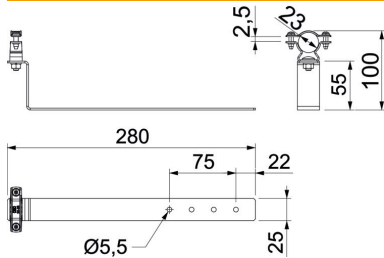

Length	280 mm
Dimension L	2.5 mm

### Technical data

Connection	Round conductor
Application	Pitched roof
Conductor fastening type	With clamp clip
Conductor diameter, min.	23
Mounting type	Screw-on
Mounting height	55 mm
Material of the holder	Rustproof steel (V2A)
Material of the support	Rustproof steel (V2A)