

Technical data sheet

Insulated air-termination rod for inner-routed isCon conductor with side exit

Item number: 5408940



- For installation of the OBO isCon® Pro+ conductor in the pipe
- With side conductor outlet matching isFang air-termination rod stand with side outlet, type isFang 3B-A
- Suitable for wind loads according to Eurocode 1: DIN EN 1991-1-4
- Inclusive connection element (type isCon IN connect)
- Inclusive potential connection (type isCon In PAE)
- Aluminium standpipe and air-termination tip
- Centre section made of fibre-glass reinforced plastic (GRP)



GFK Fibre-glass-reinforced plastic

Master data

Item number	5408940
Type	isFang IN-A 6000
Description 1	Insul. interception rod+outlet
Description 2	for isCon conductor, internal
Manufacturer	OBO
Dimension	6000mm
Material	Fibre-glass-reinforced plastic
Smallest sales unit	1
Unit of quantity	Piece
Weight	939 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	80,1331 kg CO2e / 1 Piece


Technical data sheet

Insulated air-termination rod for inner-routed isCon conductor with side exit

Item number: 5408940



Dimensions

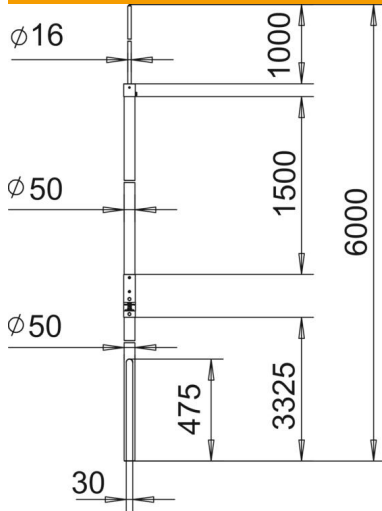

Length	6,000 mm
Dimension A	3,325 mm
Dimension B	1,000 mm
Dimension d min.	50 mm
Dimension H	1,500 mm
Dimension L	6,000 mm

Technical data

Connection	Round conductor
Version for	Air-termination rod
High voltage-resistant, insulated version	yes